


# Premium luminaire

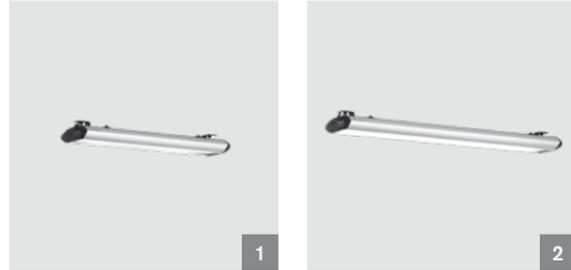

## Technical data

	Order details	Power consumption	Nominal voltage	Dimensions (LxWxH)	Colour temperature	Order number
1	Premium luminaire 1	18 W	220 – 240 V	656 x 187 x 50 mm	4000 K	N0867
2	Premium luminaire 2	26 W	220 – 240 V	956 x 187 x 50 mm	4000 K	N0868

Other versions available on request, e.g. with daylight, dimming function, radio control, through-wiring or ESD version.

# Standard luminaire



## Technical data

	Order details	Power consumption	Nominal voltage	Dimensions (LxWxH)	Colour temperature	Illumination intensity (at 1m)	Order number
3	Standard luminaire 1 Fix (l = 661 mm)	21 W	220 – 240 VAC	626 x 51 x 38 mm	4000 K	903 lx	N3946
3	Standard luminaire 2 Fix (l = 1171 mm)	40 W	220 – 240 VAC	1136 x 51 x 38 mm	4000 K	1841 lx	N3948
3	Standard luminaire 1 Fix cold white (l = 661 mm)	21 W	220 – 240 VAC	626 x 51 x 38 mm	5700 K	903 lx	N3949
3	Standard luminaire 2 Fix cold white (l = 1171 mm)	40 W	220 – 240 VAC	1136 x 51 x 38 mm	5700 K	1841 lx	N3950
4	Standard luminaire 1 Fix ESD (l = 661 mm)	21 W	220 – 240 VAC	626 x 51 x 38 mm	4000 K	861 lx	N3951
4	Standard luminaire 2 Fix ESD (l = 1171 mm)	40 W	220 – 240 VAC	1136 x 51 x 38 mm	4000 K	1756 lx	N3952
5	Standard luminaire 1 Fix SC (l = 661 mm)	21 W	220 – 240 VAC	626 x 51 x 38 mm	4000 K	903 lx	N3953
5	Standard luminaire 2 Fix SC (l = 1171 mm)	40 W	220 – 240 VAC	1136 x 51 x 38 mm	4000 K	1841 lx	N3954
6	Standard light 1 Fix M12 (l = 661 mm)	27 W	24 VDC	626 x 51 x 38 mm	4000 K	882 lx	N3955
6	Standard luminaire 2 Fix M12 (l = 1171 mm)	52 W	24 VDC	1136 x 51 x 38 mm	4000 K	1764 lx	N3956
7	Articulated arm light	17 W	220 – 240 VAC	889 x 33 x 26 mm	4000 K	2480 lx	N3960
7	Cold white articulated arm light	17 W	220 – 240 VAC	889 x 33 x 26 mm	5000 K	2480 lx	N3961
8	Standard light, lateral	7 W	220 – 240 VAC	337 x 51 x 65 mm	4000 K	557 lx	N0246
8	Standard light, lateral ESD	7 W	220 – 240 VAC	337 x 51 x 65 mm	4000 K	531 lx	N4209
9	Mounting set for light C (2x mounting plate, 4x M6x14 screw, 2x M6 swivel-in slot nuts, 2x M6 nut)						S03-003-01
	Connection cable 4 m, Wieland GST15I3-T12						N3957
	Connection cable 1m, GST15I3 socket – plug						N3959