


## Aluminium Tubes

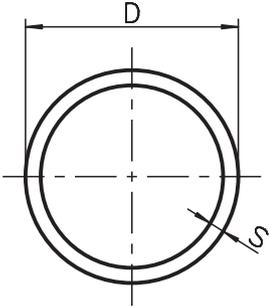

Can be supplied in warehouse length or cut to size.

Surface: untreated

Nominal Diameter	Dimension D1 x S	Weight kg/m	Order Number L = 5000 mm	Order Number cut to ... mm
12	12 x 1.5	0.130	R01-97-00/5000 mm	R01-97-02/ ... mm
20	20 x 2	0.310	R02-97-00/5000 mm	R02-97-02/ ... mm
30	30 x 2	0.480	R03-97-00/5000 mm	R03-97-02/ ... mm
40	40 x 2	0.650	R04-97-00/5000 mm	R04-97-02/ ... mm
50	50 x 3	1.210	R05-97-00/5000 mm	R05-97-02/ ... mm

For diameter D tolerances, see page 233