
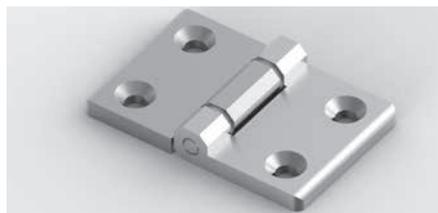


Zn-die cast hinges fixed type

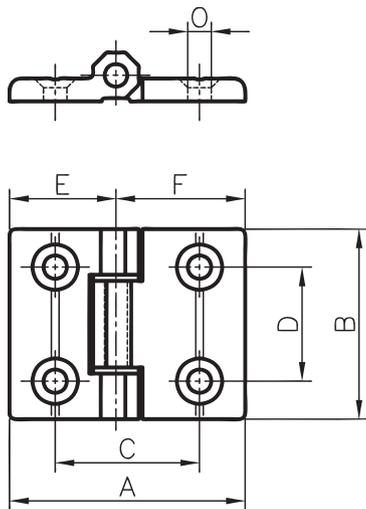

Specification

GD-Zn, nickel plated
(black powder coated on request)
Pin: steel zinc coated
washer: PA-6 white

Order data


Zn-diecasting hinges

Base	A	B	C	D	E	F	O
50	78	50	54	30	39	39	6.3
50/40	73	50	49	30	34	39	6.3
50/30	67	50	43	30	28	39	6.3
40	68	50	44	30	34	34	6.3
40/30	62	50	38	30	28	34	6.3
30	56	50	32	30	28	28	6.3
20	40	40	25	25	20	20	5.3

Al-heavy duty hinges

Base	A	B	C	D	E	F	O
50	92	100	54	75	46	46	6.3
50/40	82	100	49	75	36	46	6.3
45	72	100	49	75	24.5	24.5	6.3
40	72	100	44	75	36	36	6.3

Al-heavy duty hinges fixed type

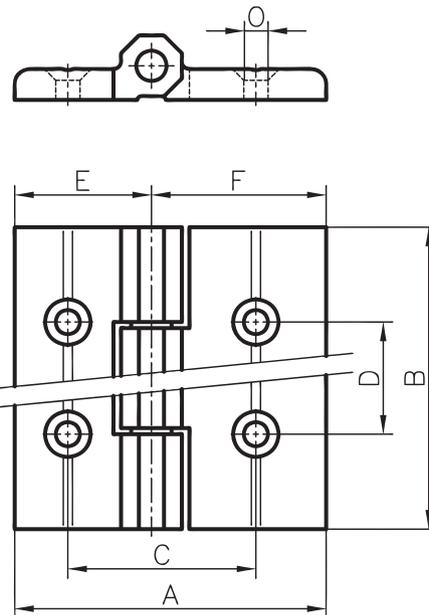

Specification

Al, anodised natural colours
Pin: steel zinc coated
bush bearing: iglidur G, grey

Order number

A60-21*
AC6-21**
AB6-21*
C60-21*
CB6-21*
B60-21*
D60-21*


* the order number for the fixing kit add

-S to the art.no.:

Example: A60-21-S

** also applicable for 45x45

Special hinges lift-off type

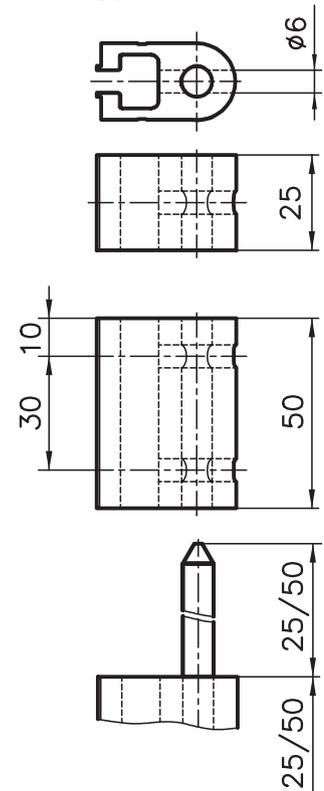

Specification

Al anodised natural colours
Pin Ø 8mm: steel zinc coated

Order data

	Order number
	L = 25 L = 50
Hinge component , no pin	A60-50 A60-55
Hinge component , with a pin	A60-51 A60-56