

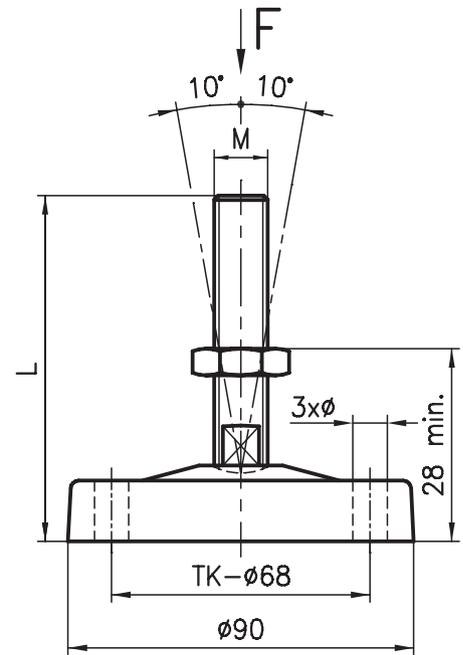


## Levelling feet

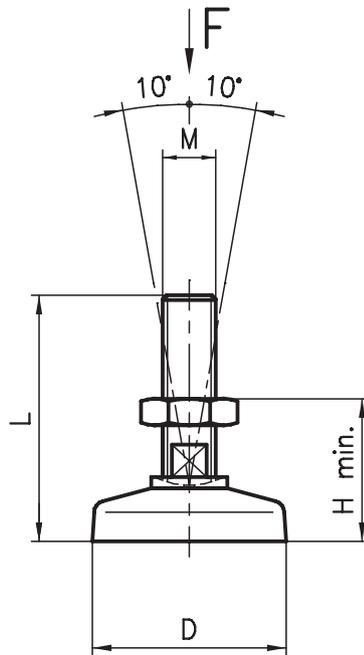

### Application

Cup: glass-filled Polyamide (PA-GF) black  
 Bolt/locknut: 8.8 steel, zinc-coated  
 Anti-slide pad: NBR rubber

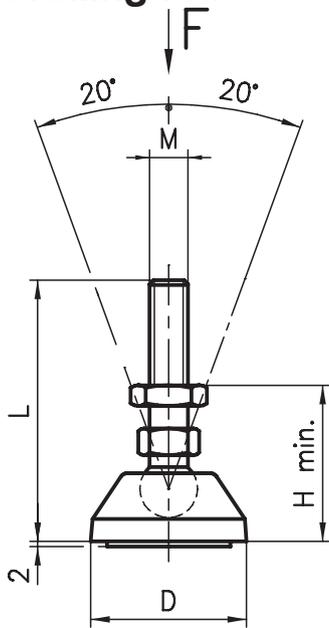

### Order data

MxL	D	H	F	Order number
M6x57	19	25	500 N	B43-02
M10x75	29	30	2000 N	B43-10
M10x75	39	30	3000 N	B43-11
M10x75	49	30	3000 N	B43-12
M16x155	39	40	8000 N	B43-16

Other dimensions or special feet are available on demand.

### Application

These continuously variable levelling feet are used for many different applications. The cup is attached in such a way as to compensate for uneven floors.

### Specification

Cup: PA-GF black  
 Bolt/locknut: 8.8 steel, zinc-coated



### Order data

MxL	D	H	F	Order number
M10x70	50	30	2500 N	B42-50
M10x122	50	30	2500 N	B42-00
M14x65	50	25	3000 N	B42-54
M14x115	50	25	3000 N	B42-14
M16x65	50	25	3500 N	B44-50
M16x115	50	25	3500 N	B44-00

### Specification

Cup: PA-GF black or aluminium  
 bolt : 8.8 steel, zinc-coated



### Order data

MxL	Ø	F	PA-GF	Aluminium
M14x70	9	4000 N	B45-54	B45-55
M14x120	9	4000 N	B45-14	B45-56
M16x70	9	5000 N	B45-50	B45-03
M16x120	9	5000 N	B45-00	B45-04
M14x70	9	8000 N		B45-51
M14x70	-	8000 N		B45-52
M14x120	9	8000 N		B45-01
M14x120	-	8000 N		B45-02
M16x70	9	10'000 N		B45-01
M16x70	-	10'000 N		B45-02
M16x120	9	10'000 N		B45-01
M16x120	-	10'000 N		B45-02