



Four sided softline extrusion 40x40 type C10-0

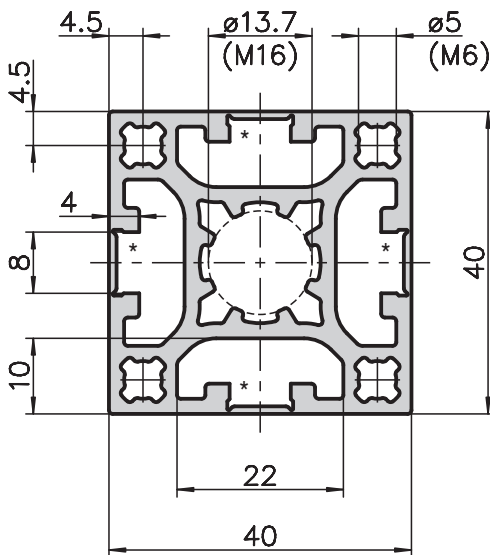

Application

These extrusions are used in clean-room applications, in the food industry or anywhere where no open slots are to be found and where smooth surfaces are desired. Thanks to the rip off slots, all connection options are guaranteed.

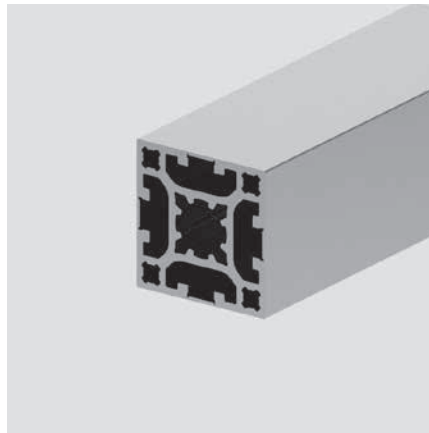

Technical data

$I_{x,y}$	=	9.6 cm ⁴
$W_{x,y}$	=	4.75 cm ³
Cross-section area	=	5.97 cm ²
Weight	=	1.6 kg/m


Order data	Order number
------------	--------------

Four sided softline extrusion 40x40
Standard length 5000 mm C10-0-00/5000

Four sided softline extrusion 40x40
Cut to length C10-0-02-02/...


Extra machining Pages 57-61

**Four sided softline extrusion
40x80 type C10-3**

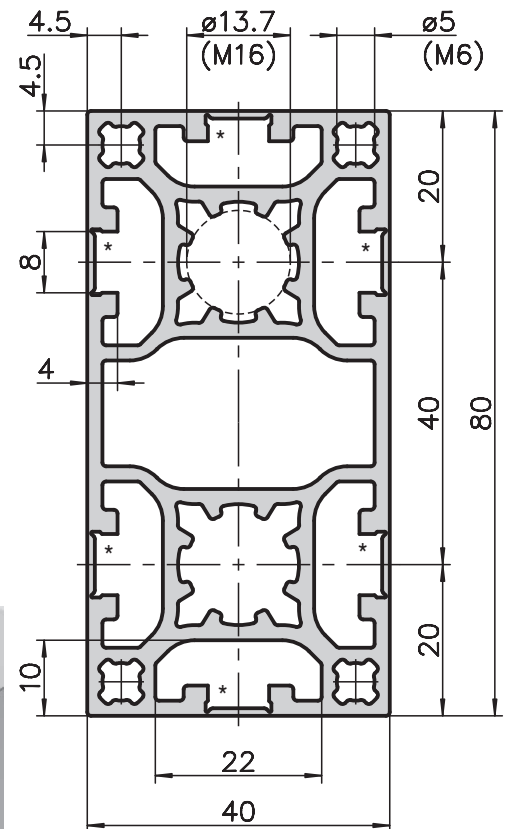

Application

Same intended use as C10-0 but with greater stability because of the dimension 40x80mm.

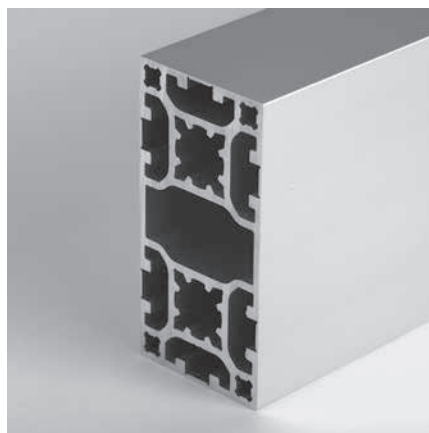

Technical data

I _x	=	69.73 cm ⁴
I _y	=	18.52 cm ⁴
W _x	=	17.43 cm ³
W _y	=	9.26 cm ³
Cross-section area	=	10.34 cm ²
Weight	=	2.8 kg/m

Order data	Order number
------------	--------------

Four sided softline extrusion 40x80
Standard length 5000 mm C10-3-00/5000

Four sided softline extrusion 40x80
Cut to length C10-3-02-02/...

Extra machining Pages 57-61