


Four sided softline extrusion 45x45 Type E10-1

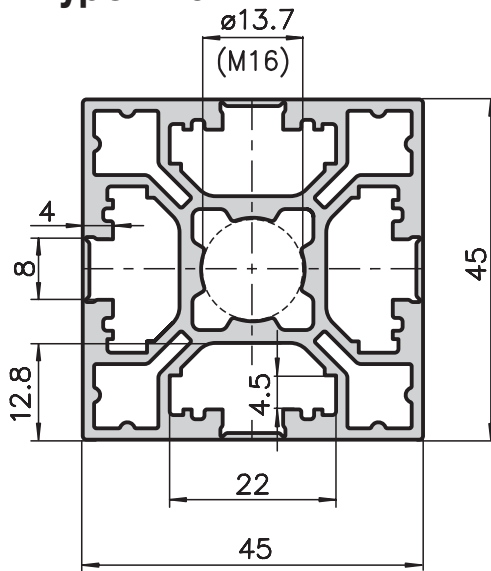

Application

The four sided softline extrusion 45x45 features an absolutely smooth surface. For this reason it is ideally suitable for clean room technology. The stable and elegant profile is easily washable. All connections are possible, thanks to the rip off slots.


Technical data

$I_{x, y}$	=	14.07 cm ⁴
$W_{x, y}$	=	6.25 cm ³
Cross-section area	=	6.75 cm ²
Weight	=	2.07 kg/m

Order data Order number

Four sided softline extrusion 45x45	
Standard length 5000 mm	E10-1-00/5000
Four sided softline extrusion	
Cut to length	E10-1-02-02/...
Extra machining	Pages 57-61

Light extrusion 45x45 Type E02-1

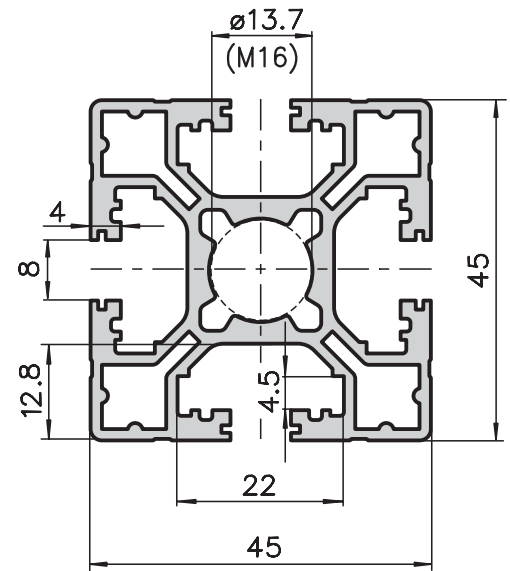

Application

With this light extrusion 45x45 you have many possible applications. The light-weight design offers a stable construction at an unbeatable price. This profile is particularly suitable for protective enclosures.

Technical data

$I_{x, y}$	=	13.16 cm ⁴
$W_{x, y}$	=	5.85 cm ³
Cross-section area	=	6.37 cm ²
Weight	=	1.72 kg/m

Order data Order number

Light extrusion 45x45	
Standard length 5000 mm	E02-1-00/5000
Light extrusion 45x45	
Cut to length	E02-1-02-02/...
Extra machining	Pages 57-61