



直线导轨

直线导轨夹具 中载·重载直线导轨用



型号
AGSCN24



型号区分：
交货期 7 天发货




耐热温度：-20~80℃

代码		零件名称	材质	表面处理
旋钮型	把手型			
AGSCN	AGSCK	① 主体	S45C	无电解镀镍
		② 左右螺丝	SCM435	发黑
		③ 夹紧块	S45C	—



■ 紧固扭矩和保持力
● 7N·m以上
保持力(参考) 1200N
● 夹紧块开度范围
H24...10~22mm H36...17~36mm
H28...14~28mm H42...21~56mm
H30...15~30mm H42G...21~56mm
H33...16~40mm

■ 组装尺寸


旋钮型 AGSCN

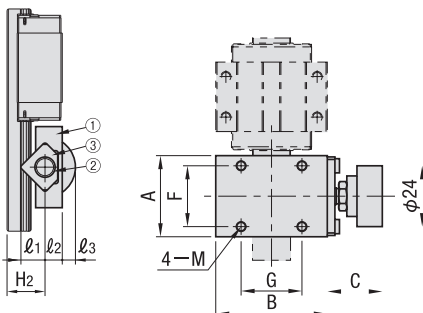

夹紧把手型 AGSCK

 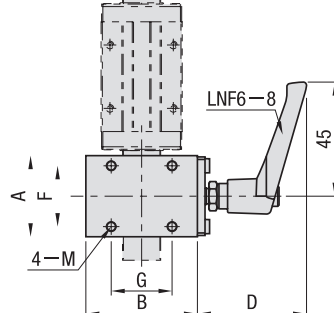

(AGSCN24 型)

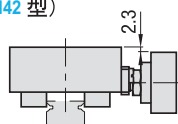

型号		A	B	F	G	C		E	T	H1	H2	l1	l2	l3	M (粗牙螺纹)
代码						AGSCN	AGSCK								
AGSCN AGSCK	24	32	44	24	24	21.7	43	10	10.5	16.3	17.2	9.5	6.8	5.2	M4
	28	35	50	25	25	21.7	43	10	11.5	17.3	20.2	9.5	7.8	4.2	M5
	30	38	54	28	28	21.7	43	11	11.0	18.3	22.7	11.0	7.3	4.7	M5
	33	38	62	26	26	21.7	43	10	14.0	19.8	22.7	9.5	10.3	1.7	M6
	36	42	60	30	30	21.7	43	11	13.0	20.3	26.7	11.0	9.3	2.7	M6
	42	46	80	32	32	21.7	43	11	18.0	25.3	27.7	11.0	14.3	—	M8

